



Product Information Sheet

Draka Part Number 80-007-S:


Hoist rope, 8x19 Seale with natural fiber core, 11 mm diameter, 1370/1770 N/mm² tensile strength, right regular lay, 13125 lbf minimum breaking force, 0.29 lbs/foot net weight, preformed, bright (uncoated) finish, 152 load bearing wires in the outer strands, diameter tolerance = maximum 5% with no load and minimum 0% at 10% of minimum breaking load.

Información del Producto

Número de parte Draka: 80-007-S

Descripción del producto:

- **Tipo de cable:** Cuerda de izaje (hoist rope)
- **Construcción:** 8x19 Seale con alma de fibra natural
- **Diámetro:** 11 mm
- **Resistencia a la tracción:** 1370/1770 N/mm²
- **Sentido de la hélice:** Hélice regular a la derecha (Right Regular Lay)
- **Fuerza mínima de ruptura:** 13.125 lbf (libras-fuerza)
- **Peso neto:** 0,34 lbs/pie
- **Forma:** Prefabricada (preformed)
- **Acabado superficial:** Brillante (sin recubrimiento)
- **Número de alambres portantes de carga:**
152 alambres en las capas exteriores
- **Tolerancia de diámetro:**
Máxima: +5% sin carga
Mínima: 0% bajo el 10% de la carga mínima de ruptura

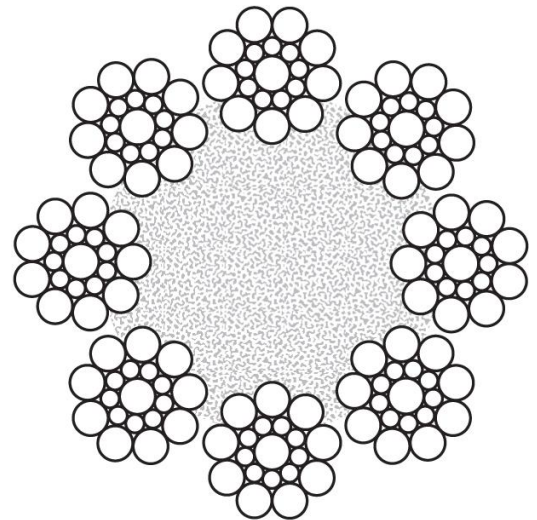

Consulte nuestro directorio de ejecutivos comerciales en: <https://co.prysmian.com/es/contáctenos>

Copyright 2018 Gustav Wolf USA